

**Part No:** 280-101822

**Fabricated Low Head PIP**

**Saddles**

**Desc:** 12X10 PVC SADDLE SOC LOW HEAD PIP

**MSRP:** 66.58

**Part Code:** 300

**Weight(lbs):** 2.094

**Weight(kg):** 0.95

**Weight(gm):** 950


**Size:** 12 X 10

**Color:** WHITE

**Material:** PVC

**Type** Saddle-Reducer

**Connection** Socket

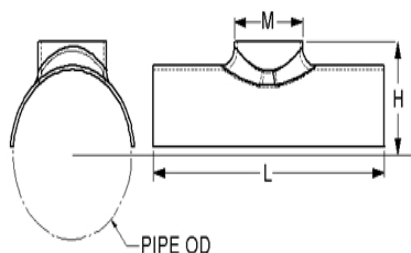

**L** = 17

**M** = 10-7/16

**H** = 8

## Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  inch. & larger  $\pm 1/2$  inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.
- L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.
- M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.
- N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.
- W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

