

Part No: 280-101829

Fabricated Low Head PIP

Saddles

Desc: 18X15 PVC SADDLE SOC LOW HEAD PIP

MSRP: 170.26

Part Code: 300

Weight(lbs): 6.57

Weight(kg): 2.98

Weight(gm): 2980


Size: 18 X 15

Color: WHITE

Material: PVC

Type Saddle-Reducer

Connection Socket

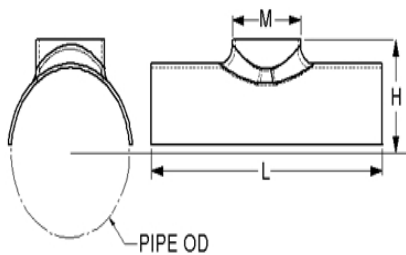

H = 11-1/4

L = 25

M = 15-11/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

