

Part No: 280-101886

Fabricated Low Head PIP

Saddles

Desc: 10X2 PVC STB SADDLE SOC LOW HEAD PIPXIPS

MSRP: 39.01

Part Code: 300

Weight(lbs): 0.816

Weight(kg): 0.37

Weight(gm): 370


Size: 10 X 2

Color: WHITE

Material: PVC

Type Stub Saddle-Reducer

Connection Socket

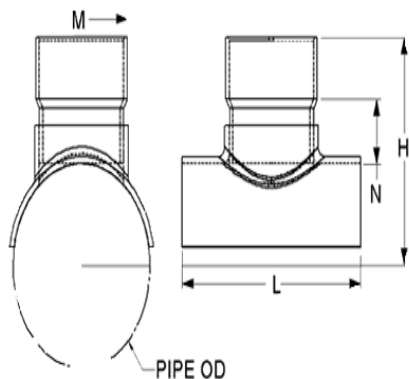

H = 9-1/8

L = 8-1/2

M = 2-11/16

N = 2-1/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

