

**Part No:** 280-101889

**Fabricated Low Head PIP**

**Saddles**

**Desc:** 18X2 PVC STB SADDLE SOC LOW HEAD PIPXIPS

**MSRP:** 45.02

**Part Code:** 300

**Weight(lbs):** 0.882

**Weight(kg):** 0.4

**Weight(gm):** 400


**Size:** 18 X 2

**Color:** WHITE

**Material:** PVC

**Type** Stub Saddle-Reducer

**Connection** Socket

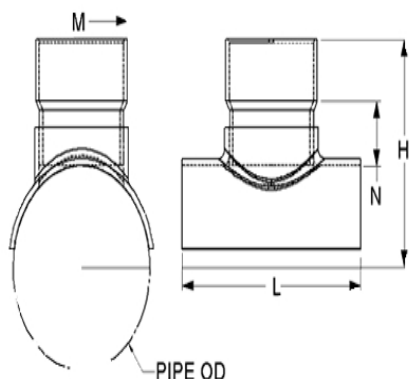

**H** = 13-3/16

**L** = 9

**M** = 2-11/16

**N** = 2-1/4

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  inch & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

