

Part No: 280-101955

Fabricated Low Head PIP

Saddles

Desc: 20X20 PVC STUB SADDLE SOC LOW HEAD PIP

MSRP: 636.16

Part Code: 300

Weight(lbs): 30.305

Weight(kg): 13.746

Weight(gm): 13746


Size: 20 X 20

Color: WHITE

Material: PVC

Type Stub Saddle - Same Size

Connection Socket

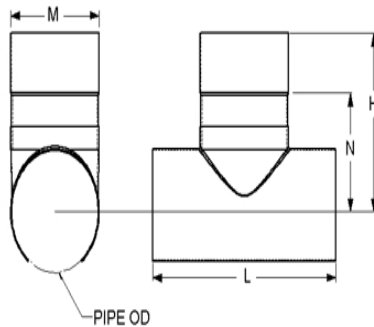

H = 21-15/16

L = 38

M = 20-13/16

N = 11-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

