

Part No: 2880-72430

Fabricated Low Head PIP

Risers

Desc: 15X4 PVC ORCHARD RISERX30 LOW HEAD PIP

MSRP: 64.54

Part Code: 301

Weight(lbs): 3.086

Weight(kg): 1.4

Weight(gm): 1400


Size: 15 X 4

Color: WHITE

Material: PVC

Type Orchard Riser

Connection Saddle X Riser

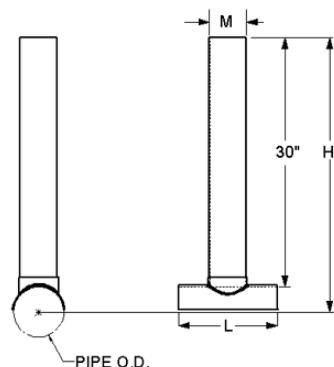

H = 37-13/16

L = 8-3/4

M = 4-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

