

Part No: 2881-82032

Fabricated Low Head PIP

Risers

Desc: 20X10X15 PVC EROSION POT RISERX32 LHD

MSRP: 252.2

Part Code: 301

Weight(lbs): 14.251

Weight(kg): 6.464

Weight(gm): 6464


Size: 20 X 10 X 15

Color: WHITE

Material: PVC

Type Erosion Pot Riser

Connection Saddle X Riser X Pot

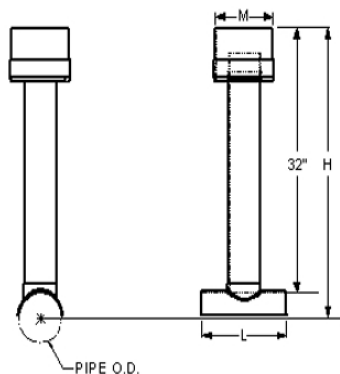

H = 42-5/16

L = 17

M = 15-5/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

