

Part No: 300-101800

Fabricated PIP

Saddles

Desc: 12X3 PVC SADDLE SOC 100PIPXIPS

MSRP: 117.44

Part Code: 320

Weight(lbs): 4.784

Weight(kg): 2.17

Weight(gm): 2170

Size: 12 X 3

Color: WHITE


Material: PVC

Materials PVC 100

Connection Socket

Type Standard PIP X IPS

NOTE NOT PRESSURE RATED

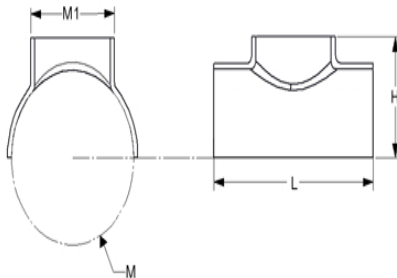

H = 7-9/16

M = 12-1/4

M1 = 4-1/8

L = 15

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

