

Part No: 300-101804

Fabricated PIP

Saddles

Desc: 6X4 PVC SADDLE SOC 100PIPXIPS

MSRP: 136.99

Part Code: 320

Weight(lbs): 0.772

Weight(kg): 0.35

Weight(gm): 350

Size: 6 X 4

Color: WHITE


Material: PVC

Materials PVC 100

Connection Socket

Type Standard PIP X IPS

NOTE NOT PRESSURE RATED

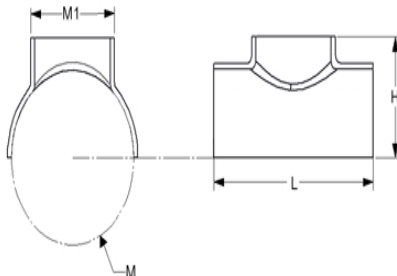

H = 4-3/16

M = 6-1/8

M1 = 4-3/4

L = 12

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

