

Part No: 300-101811

Fabricated PIP

Saddles

Desc: 8X6 PVC SADDLE SOC 100PIP

MSRP: 156.58

Part Code: 320

Weight(lbs): 2.778

Weight(kg): 1.26

Weight(gm): 1260

Size: 8 X 6

Color: WHITE


Material: PVC

Materials PVC 100

Connection Socket

Type Standard PIP X IPS

NOTE NOT PRESSURE RATED

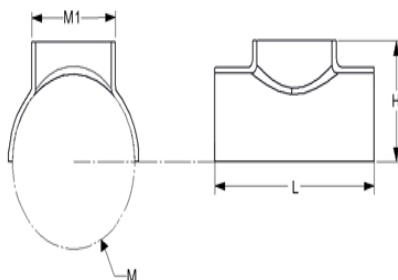

H = 5-1/2

M = 8-3/16

M1 = 6-9/16

L = 20

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

