

Part No: 3028B-100X18

Fabricated PIP

Bolted Compression Couplings

Desc: 10 PVC ZINC BOLT RPR COUPX18 SBR 100PIP

MSRP: 1827.2

Part Code: 320

Weight(lbs): 27.337


Weight(kg): 12.4

Weight(gm): 12400

Size: 10

Color: GRAY

Material: PVC

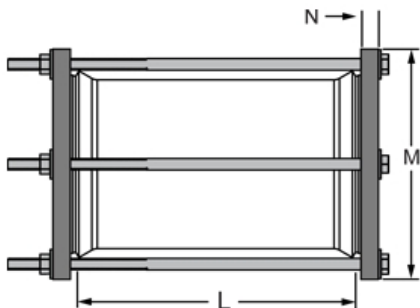

Type Compression Coupling
Connection SBR x 100 PIP
Hardware ZINC
Pressure Rating 100 psi
Length 18'

L = 18

M = 14-3/16

N = 3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

