

Part No: 3028B-100X18S

Fabricated PIP

Bolted Compression Couplings

Desc: 10 PVC 316SS BOLT RPR COUPX18 SBR 100PIP

MSRP: 2023.79

Part Code: 320

Weight(lbs): 28.329


Weight(kg): 12.85

Weight(gm): 12850

Size: 10

Color: GRAY

Material: PVC

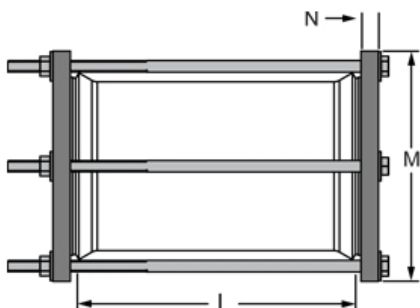

Type Compression Coupling
Connection SBR x 100 PIP
Hardware SS316
Pressure Rating 100 psi
Length 18'

L = 18

M = 14-3/16

N = 3/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

