

Part No: 3622-010FG

FlameGuard®

Drain Valves

Desc: 1 PVC TU2K STDBV SXS PVCXFLMGRDCPVC EPDM

MSRP: 72.4

Part Code: 077

Weight(lbs): 0.75

Weight(kg): 0.34

Weight(gm): 340

Size: 1

Color: Gray/Orange


Material: CPVC

Connection Socket x Socket

Type Standard

O-Ring EPDM

Note Not UL® Listed

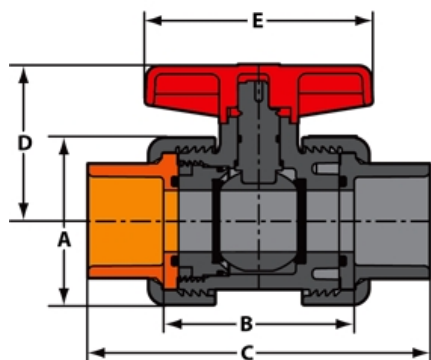

A = 2-5/8

B = 2-15/16

C = 5-3/16

D = 2-5/16

E = 3-5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

