

Part No: 3623-040C

Valves

True Union Ball Valve

Desc: 4 CPVC TU2K STANDARD BV FLANGED EPDM

MSRP: 2298.63

Part Code: 611

Weight(lbs): 19.429


Weight(kg): 8.813

Weight(gm): 8813

Size: 4"

Color: GRAY

Material: CPVC

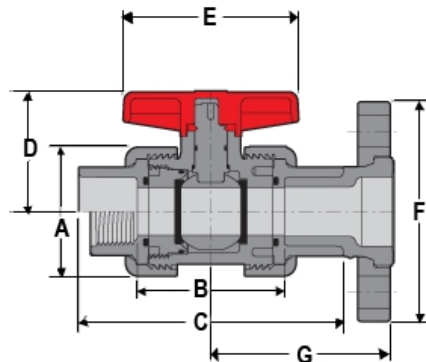


Type TU 2000 - Standard
O-Ring EPDM
Connection Flanged
Pressure Rating 150 psi @ 73° F

A = 7-3/4 **B** = 7-13/32 **C** = 11-15/16 **D** = 6-1/8 **E** = 9
F = 9- 1/16 **G** = 7-1/2 **Cv** = 1952
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
L = Overall length of fittings; ± 1/16 inch.
M = Outside diameter of socket/thread hub; ± 1/16 inch.
N = Socket bottom to socket bottom; couplings; ± 1/16 inch.
W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

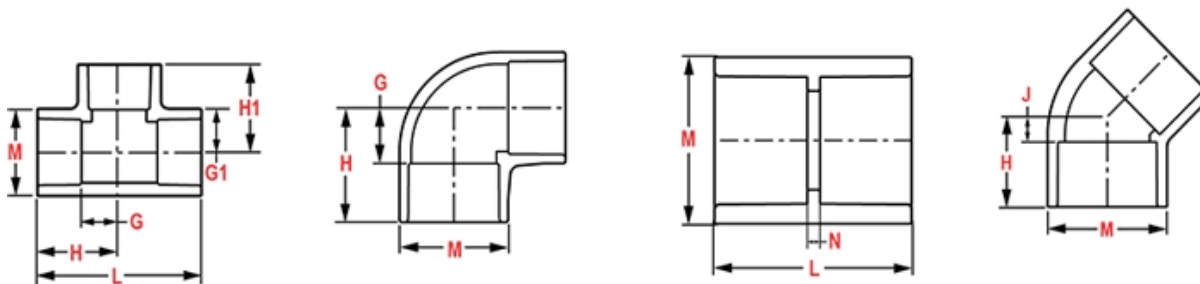

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006