

Part No: 3631-005CSR

Valves

True Union Ball Valve

Desc: 1/2 CPVC TU2K STANDARD BV SR/THD FKM

MSRP: 99.41

Part Code: 610

Weight(lbs): 0.403


Weight(kg): 0.183

Weight(gm): 183

Size: 1/2"

Color: GRAY

Material: CPVC

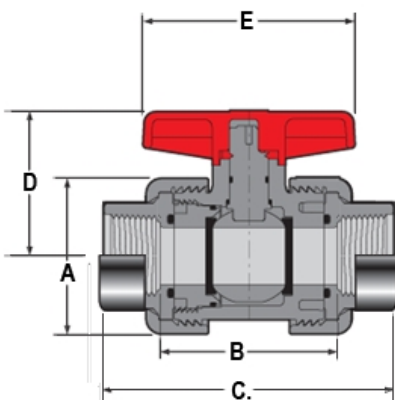

Type TU 2000 - Standard
O-Ring FKM
Connection SR Fipt
Pressure Rating 235 psi @ 73° F

A = 1- 7/8

B = 2- 7/16

C = 3-13/16

D = 1- 5/8

E = 2- 1/2

Cv = 29

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

