

Part No: 3631-007CSR

Valves

True Union Ball Valve

Desc: 3/4 CPVC TU2K STANDARD BV SR/THD FKM

MSRP: 126.91

Part Code: 610

Weight(lbs): 0.595


Weight(kg): 0.27

Weight(gm): 270

Size: 3/4"

Color: GRAY

Material: CPVC

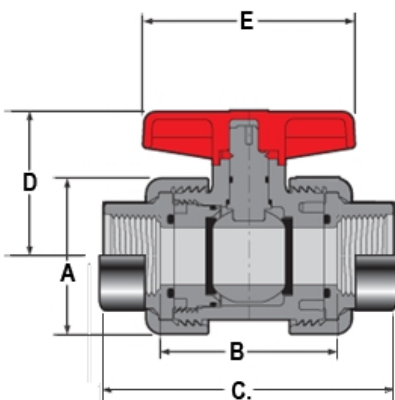

A = 2- 1/4

B = 2- 3/4

C = 4- 1/4

D = 2

E = 3

Cv = 63

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

