

**Part No:** 3631-025CSR

**Valves**

**True Union Ball Valve**

**Desc:** 2-1/2 CPVC TU2K STANDARD BV SR/THD FKM

**MSRP:** 772.01

**Part Code:** 611

**Weight(lbs):** 7.932


**Weight(kg):** 3.598

**Weight(gm):** 3598

**Size:** 2-1/2"

**Color:** GRAY

**Material:** CPVC

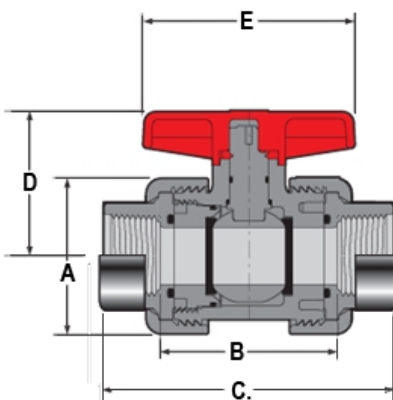

**Type** TU 2000 - Standard  
**O-Ring** FKM  
**Connection** SR Fipt  
**Pressure Rating** 150 psi @ 73° F

**A** = 6- 3/16

**B** = 6- 7/8

**C** = 9-11/16

**D** = 5- 7/8

**E** = 7- 5/8

**Cv** = 856

**Values**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

