

Part No: 3631-040CSR

Valves

True Union Ball Valve

Desc: 4 CPVC TU2K STANDARD B/V SR/THD FKM

MSRP: 1606.03

Part Code: 611

Weight(lbs): 14.092


Weight(kg): 6.392

Weight(gm): 6392

Size: 4"

Color: GRAY

Material: CPVC

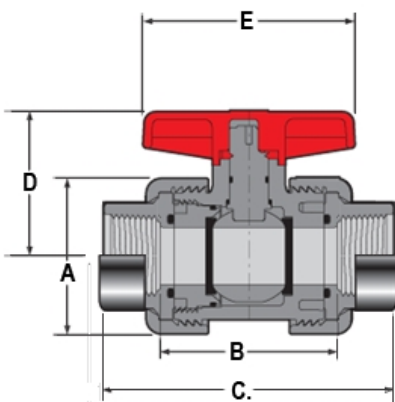

Type TU 2000 - Standard
O-Ring FKM
Connection SR Fipt
Pressure Rating 150 psi @ 73° F

A = 7- 5/8

B = 7- 5/16

C = 10- 1/4

D = 6- 3/4

E = 8- 3/8

Cv = 2865

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

