

Part No: 3633-020

Valves

True Union Ball Valve

Desc: 2 PVC TU2K STANDARD BV FLANGED FKM

MSRP: 365.69

Part Code: 608

Weight(lbs): 4.537


Weight(kg): 2.058

Weight(gm): 2058

Size: 2"

Color: GRAY

Material: PVC

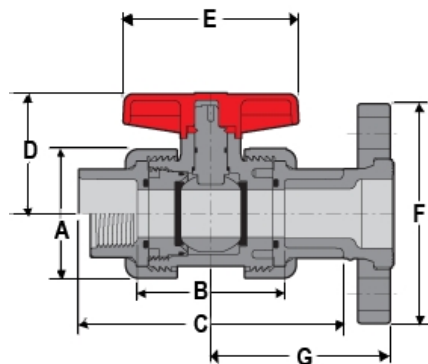

Type TU 2000 - Standard
O-Ring FKM
Connection Flanged
Pressure Rating 150 psi @ 73° F

A = 4- 1/4

B = 4- 3/4

C = 7- 3/4

D = 3- 3/4

E = 5

F = 6

G = 5- 1/4

Cv = 395
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

