

Part No: 3701-080

Fabricated DWV

Tees

Desc: 8 PVC TEE SOC SCH40

MSRP: 302.89

Part Code: 390

Weight(lbs): 15.891

Weight(kg): 7.208

Weight(gm): 7208

Size: 8


Color: WHITE

Material: PVC

Type Standard Vent Tee

Schedule SCH 40 DWV

Connection Socket x Socket x Socket

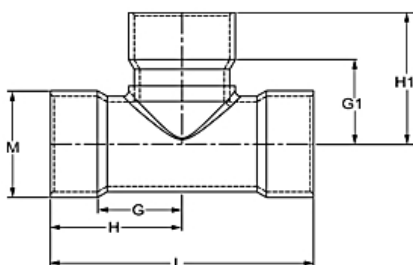

G = 7-5/16

G1 = 7-5/16

H = 11-9/16

H1 = 11-9/16

L = 23-1/8

M = 9-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

