

Part No: 3701-530

Fabricated DWV

Tees

Desc: 6X3 PVC RED TEE SOC SCH40

MSRP: 168.78

Part Code: 390

Weight(lbs): 5.512


Weight(kg): 2.5

Weight(gm): 2500

Size: 6"X6"X3"

Color: WHITE

Material: PVC

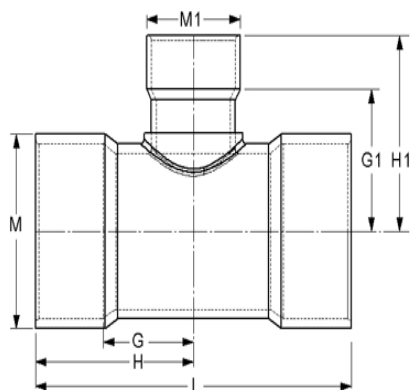

Type Reducing Vent Tee
Schedule SCH 40 DWV
Connection Socket x Socket x Socket

G = 4-5/8

G1 = 6-1/16

H = 7-7/8

H1 = 8-5/16

L = 15-3/4

M = 7-3/16

M1 = 3-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

