

Part No: 3701-578

Fabricated DWV

Tees

Desc: 8X2 PVC RED TEE SOC SCH40

MSRP: 188.92

Part Code: 390

Weight(lbs): 8.113


Weight(kg): 3.68

Weight(gm): 3680

Size: 8"X8"X2"

Color: WHITE

Material: PVC

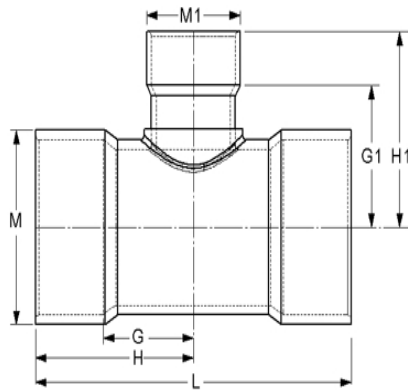

Type Reducing Vent Tee
Schedule SCH 40 DWV
Connection Socket x Socket x Socket

G = 4-1/16

G1 = 6-1/4

H = 8-5/16

H1 = 8

L = 16-5/8

M = 9-1/4

M1 = 2-11/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

