

Part No: 3701-764

Fabricated DWV

Tees

Desc: 16X14 PVC RED TEE SOC SCH40

MSRP: 2137.53

Part Code: 390

Weight(lbs): 62.417


Weight(kg): 28.312

Weight(gm): 28312

Size: 16 X 14

Color: WHITE

Material: PVC

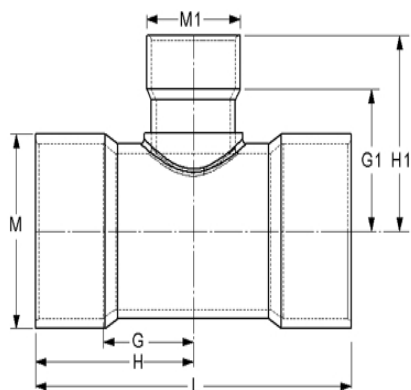

Type Reducing Vent Tee
Schedule SCH 40 DWV
Connection Socket x Socket x Socket

G = 10-3/8

G1 = 11-15/16

H = 18-3/8

H1 = 18-15/16

L = 36-3/4

M = 17

M1 = 14-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

