

Part No: 3701-918

Fabricated DWV

Tees

Desc: 24X18 PVC RED TEE SOC SCH40

MSRP: 4036.9

Part Code: 390

Weight(lbs): 177.324


Weight(kg): 80.433

Weight(gm): 80433

Size: 24 X 18

Color: WHITE

Material: PVC

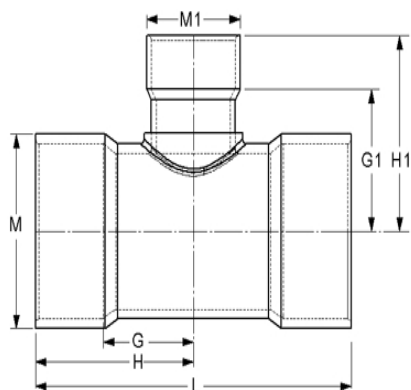

Type Reducing Vent Tee
Schedule SCH 40 DWV
Connection Socket x Socket x Socket

G = 14-1/8

G1 = 16-1/4

H = 26-1/8

H1 = 25-1/4

L = 52-1/4

M = 25-3/8

M1 = 19-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

