

Part No: 3706-120

Fabricated DWV

Elbows

Desc: 12 PVC 90 ELL SOC SCH40

MSRP: 620.07

Part Code: 390

Weight(lbs): 30.697

Weight(kg): 13.924

Weight(gm): 13924

Size: 12


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket x Socket

Angle 90°

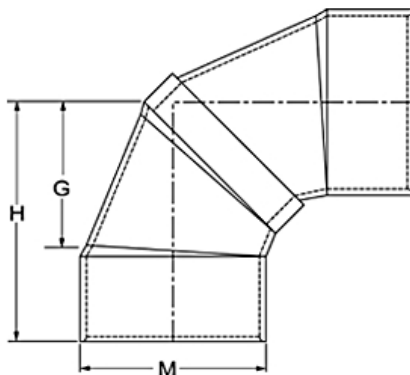

$$G = 11-3/16$$

$$H = 17-7/16$$

$$M = 13-9/16$$

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

