

**Part No:** 3711-080

**Fabricated DWV**

**Elbows**

**Desc:** 8 PVC 11-1/4 ELL SOC SCH40

**MSRP:** 178.21

**Part Code:** 390

**Weight(lbs):** 4.85


**Weight(kg):** 2.2

**Weight(gm):** 2200

**Size:** 8

**Color:** WHITE

**Material:** PVC

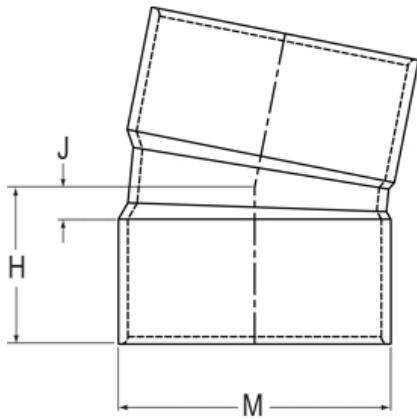

**H** = 5-5/16

**J** = 1-1/16

**M** = 9-1/4

**Schedule** SCH 40 DWV  
**Connection** Socket x Socket  
**Angle** 11-1/4°

## Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.
- L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.
- M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.
- N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.
- W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

