

**Part No:** 3711-200

**Fabricated DWV**

**Elbows**

**Desc:** 20 PVC 11 1/4 ELL SOC SCH40

**MSRP:** 1353.37

**Part Code:** 390

**Weight(lbs):** 55.175


**Weight(kg):** 25.027

**Weight(gm):** 25027

**Size:** 20

**Color:** WHITE

**Material:** PVC

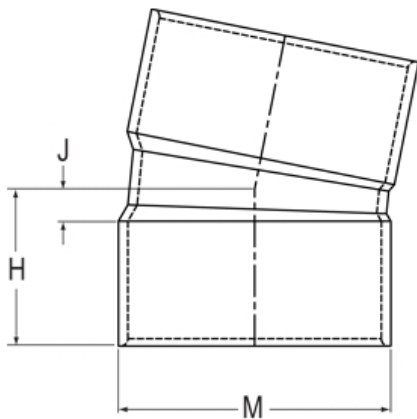

**H** = 13-1/16

**J** = 3-1/16

**M** = 21-3/16

**Schedule** SCH 40 DWV

**Connection** Socket x Socket

**Angle** 11-1/4°

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

**L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

**M** = Outside diameter of socket/thread hub; ± 1/4 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.

**W** = Height of cap; ± 1/4 inch.

## Typical Fabricated Dimension References

