

Part No: 3711-240

Fabricated DWV

Elbows

Desc: 24 PVC 11-1/4 ELL SOC SCH40 FAB

MSRP: 2419.59

Part Code: 390

Weight(lbs): 95.432


Weight(kg): 43.287

Weight(gm): 43287

Size: 24

Color: WHITE

Material: PVC

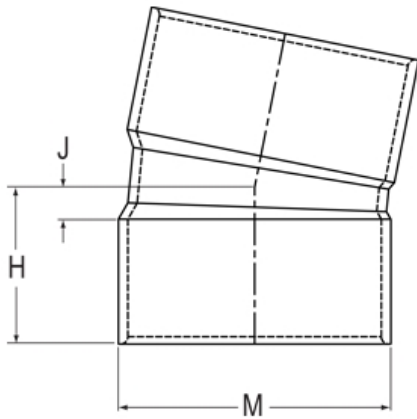

Schedule SCH 40 DWV
Connection Socket x Socket
Angle 11-1/4°

H = 15-3/4

J = 3-3/4

M = 25-3/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

