

Part No: 3715-060

Fabricated DWV

Elbows

Desc: 6 PVC 30 ELL SOC SCH40

MSRP: 105.42

Part Code: 390

Weight(lbs): 3.208

Weight(kg): 1.455

Weight(gm): 1455

Size: 6


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket x Socket

Angle 30°

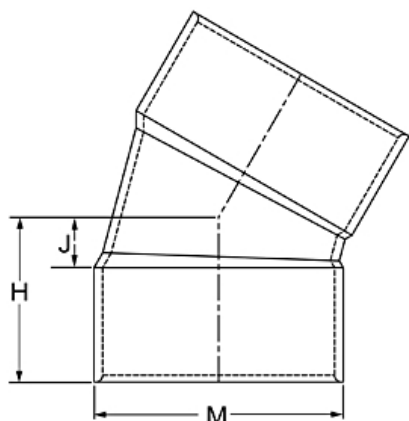

H = 4-7/8

J = 1-5/8

M = 7-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

