

Part No: 3717-100

Fabricated DWV

Elbows

Desc: 10 PVC 45 ELL SOC SCH40

MSRP: 335.57

Part Code: 390

Weight(lbs): 10.34

Weight(kg): 4.69

Weight(gm): 4690

Size: 10


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket x Socket

Angle 45°

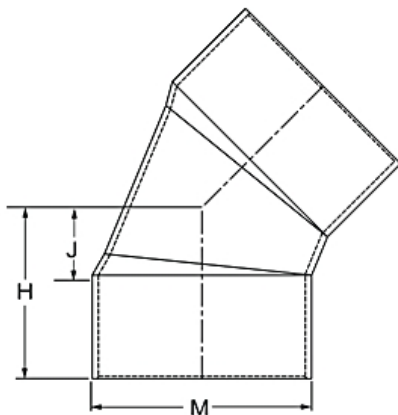

H = 8-9/16

J = 3-5/16

M = 11- 1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

