

Part No: 3717-240

Fabricated DWV

Elbows

Desc: 24 PVC 45 ELL SOC SCH40 FAB

MSRP: 2112.49

Part Code: 390

Weight(lbs): 117.888

Weight(kg): 53.473

Weight(gm): 53473

Size: 24


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket x Socket

Angle 45°

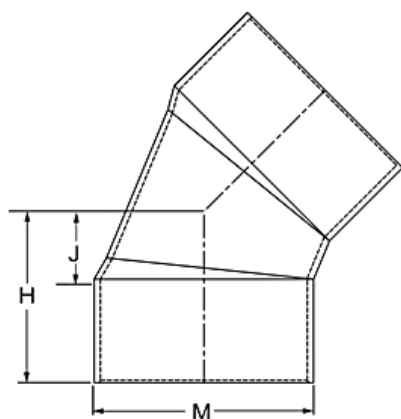

H = 19-15/16

J = 7-15/16

M = 25-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

