

Part No: 3720-100

Fabricated DWV

Crosses

Desc: 10 PVC CROSS SOC SCH40

MSRP: 785.37

Part Code: 390

Weight(lbs): 30.166

Weight(kg): 13.683

Weight(gm): 13683

Size: 10


Color: WHITE

Material: PVC

Type Standard

Schedule SCH 40 DWV

Connection Soc x Soc x Soc x Soc

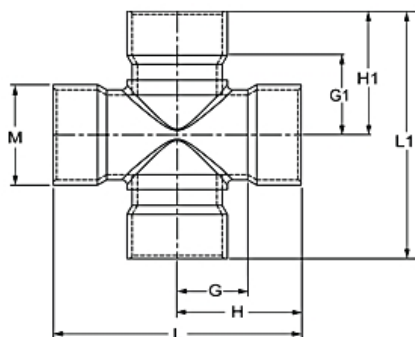

L = 28-1/2

L1 = 27-1/4

M = 11-1/2

G = 9

G1 = 8-3/8

H = 14-1/4

H1 = 13-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

