

Part No: 3720-180

Fabricated DWV

Crosses

Desc: 18 PVC CROSS SOC SCH40 FAB

MSRP: 3559.53

Part Code: 390

Weight(lbs): 130.494

Weight(kg): 59.191

Weight(gm): 59191

Size: 18


Color: WHITE

Material: PVC

Type Standard

Schedule SCH 40 DWV

Connection Soc x Soc x Soc x Soc

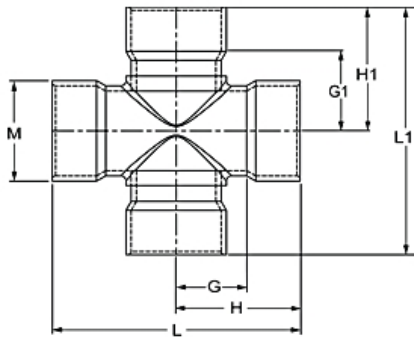

L = 44-3/4

L1 = 44-3/4

M = 19-1/8

G = 13-3/8

G1 = 13-3/8

H = 22-3/8

H1 = 22-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

