

Part No: 3720-578

Fabricated DWV

Crosses

Desc: 8X2 PVC RED CROSS SOC SCH40

MSRP: 309.77

Part Code: 390

Weight(lbs): 9.478


Weight(kg): 4.299

Weight(gm): 4299

Size: 8 X 2

Color: WHITE

Material: PVC

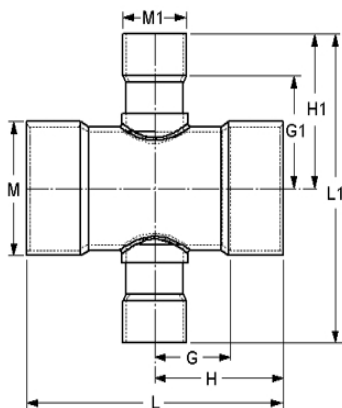

Type Reduction
Schedule SCH 40 DWV
Connection Soc x Soc x Soc x Soc

L1 = 16 M = 9-1/4 M1 = 2-11/16 G = 4-1/16 G1 = 6-1/4
 H = 8-5/16 H1 = 8 L = 16-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

