

Part No: 3720-664

Fabricated DWV

Crosses

Desc: 12X4 PVC RED CROSS SOC SCH40

MSRP: 515.84

Part Code: 390

Weight(lbs): 21.954


Weight(kg): 9.958

Weight(gm): 9958

Size: 12 X 4

Color: WHITE

Material: PVC

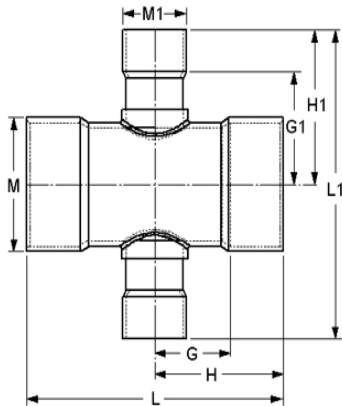

Type Reduction
Schedule SCH 40 DWV
Connection Soc x Soc x Soc x Soc

L1 = 23-1/8

M = 13-9/16

M1 = 5

G = 5-3/4

G1 = 9-5/16

H = 12

H1 = 11-9/16

L = 24

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

