

Part No: 3720-694

Fabricated DWV

Crosses

Desc: 14X4 PVC RED CROSS SOC SCH40

MSRP: 1048.97

Part Code: 390

Weight(lbs): 29.07


Weight(kg): 13.186

Weight(gm): 13186

Size: 14 X 4

Color: WHITE

Material: PVC

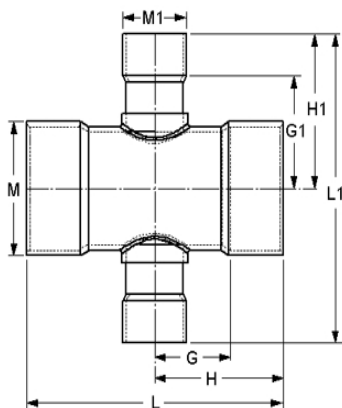

Type Reduction
Schedule SCH 40 DWV
Connection Soc x Soc x Soc x Soc

M = 14-7/8

M1 = 5

G = 5-3/8

G1 = 9-7/8

H = 12-3/8

H1 = 12-1/8

L = 24-3/4

L1 = 24-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

