

Part No: 3720-794

Fabricated DWV

Crosses

Desc: 18X14 PVC RED CROSS SOC SCH40

MSRP: 2788.49

Part Code: 390

Weight(lbs): 97.061


Weight(kg): 44.026

Weight(gm): 44026

Size: 18X14

Color: WHITE

Material: PVC

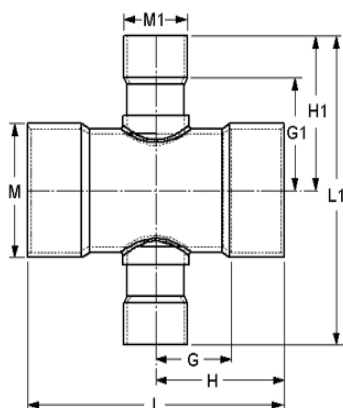


Type Reduction
Schedule SCH 40 DWV
Connection Soc x Soc x Soc x Soc

G = 11 **G1** = 12-7/8 **H** = 20-1/8 **H1** = 19-7/8 **L** = 40-1/4
L1 = 39-3/4 **M** = 19-1/8 **M1** = 14-7/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

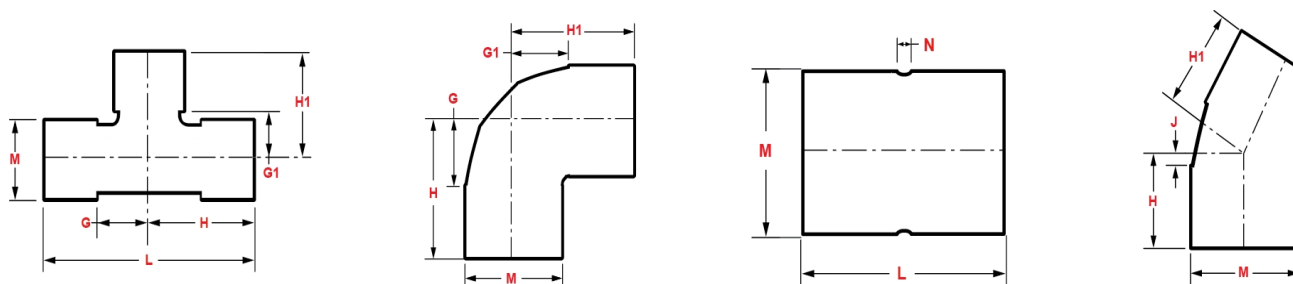

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006