

Part No: 3724-240

Fabricated DWV

Elbows

Desc: 24 PVC 60 ELL SOC SCH40

MSRP: 2509.98

Part Code: 390

Weight(lbs): 122.198

Weight(kg): 55.428

Weight(gm): 55428

Size: 24


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket x Socket

Angle 60°

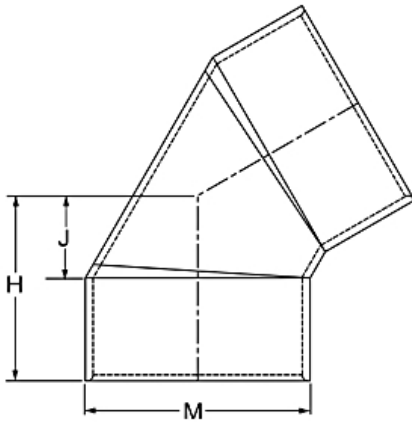

M = 25-3/8

H = 28-3/8

J = 16-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

