

Part No: 3727-140

Fabricated DWV

Elbows

Desc: 14 PVC 45 ELL SPIGOTXSOC SCH40

MSRP: 817.14

Part Code: 390

Weight(lbs): 22.02


Weight(kg): 9.988

Weight(gm): 9988

Size: 14

Color: WHITE

Material: PVC

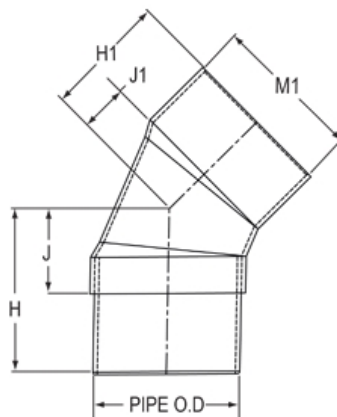

Schedule SCH 40 DWV
Connection Spigot x Socket
Angle 45° Street

H = 11-7/16

H1 = 11-7/16

J = 4-7/16

J1 = 4-7/16

M1 = 14-7/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

