

Part No: 3728-080

Fabricated DWV

Couplings

Desc: 8 PVC REPAIR COUP GSKT SCH40 DWV

MSRP: 246.89

Part Code: 390

Weight(lbs): 14.013

Weight(kg): 6.356

Weight(gm): 6356


Size: 8

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Repair

Connection Gasket x Gasket

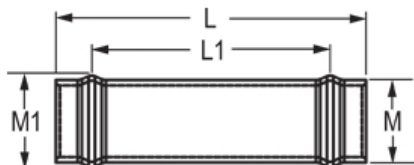

L = 26-1/8

L1 = 21-1/2

M = 9-1/16

M1 = 9-13/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

