

Part No: 3729-060IXS

Fabricated DWV

Adapters

Desc: 6 PVC ADAPTER IPSXSEWER SOC SCH40

MSRP: 87.79

Part Code: 399

Weight(lbs): 2.646

Weight(kg): 1.2

Weight(gm): 1200


Size: 6

Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection IPS Socket x SEWER Socket

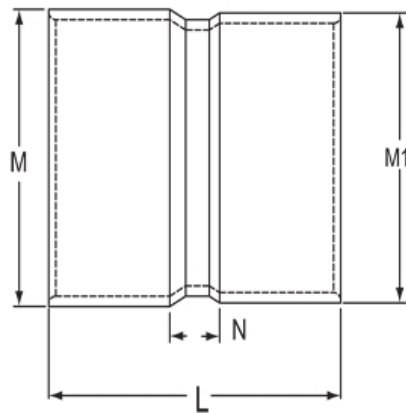

L = 7-3/4

M = 7-3/16

M1 = 6-13/16

N = 1-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

