

Part No: 3729-120

Fabricated DWV

Couplings

Desc: 12 PVC COUPLING SOC SCH40

MSRP: 210.59

Part Code: 390

Weight(lbs): 13.274

Weight(kg): 6.021

Weight(gm): 6021


Size: 12

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Standard

Connection Socket x Socket

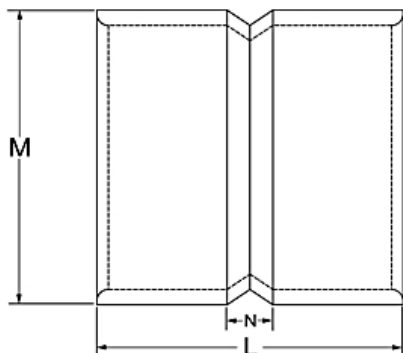

L = 14-3/4

M = 13-9/16

N = 2-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

