

Part No: 3729-120IXS

Fabricated DWV

Adapters

Desc: 12 PVC ADAPTER IPSXSWR SOC SCH40

MSRP: 337.52

Part Code: 399

Weight(lbs): 12.566

Weight(kg): 5.7

Weight(gm): 5700


Size: 12

Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection IPS Socket x SEWER Socket

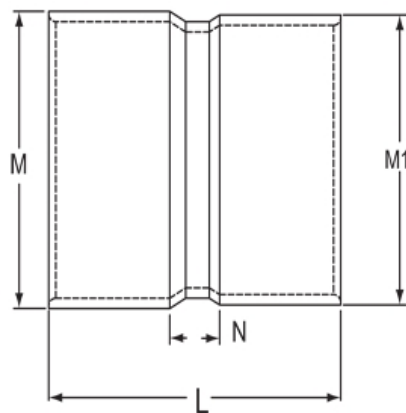

M1 = 13-5/16

N = 2-1/8

L = 14-5/8

M = 13-9/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

