

Part No: 3729-180

Fabricated DWV

Couplings

Desc: 18 PVC COUPLING SOC SCH40

MSRP: 650.43

Part Code: 390

Weight(lbs): 39.491

Weight(kg): 17.913

Weight(gm): 17913


Size: 18

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Standard

Connection Socket x Socket

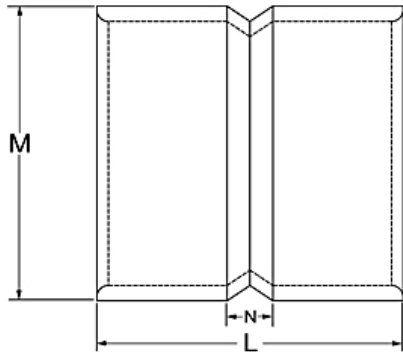

L = 21-3/4

M = 19-1/8

N = 3-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

