

Part No: 3729-528E

Fabricated DWV

Couplings

Desc: 6X2 PVC RED COUP ECC SOC SCH40

MSRP: 164.48

Part Code: 390

Weight(lbs): 3.523

Weight(kg): 1.598

Weight(gm): 1598


Size: 6"X2"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Eccentric Reducer

Connection Socket x Socket

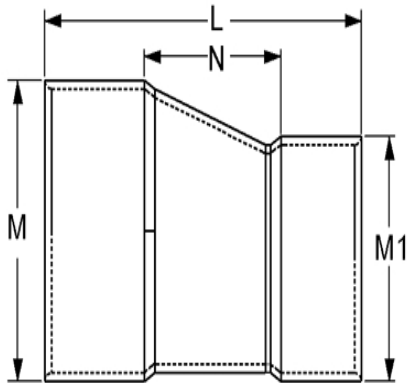

M = 7-1/8

M1 = 2-3/4

L = 15-9/16

N = 10-15/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

