

Part No: 3729-530E

Fabricated DWV

Couplings

Desc: 6X3 PVC RD COUPLING ECC SOC SCH40

MSRP: 151.52

Part Code: 390

Weight(lbs): 3.172

Weight(kg): 1.439

Weight(gm): 1439


Size: 6"X3"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Eccentric Reducer

Connection Socket x Socket

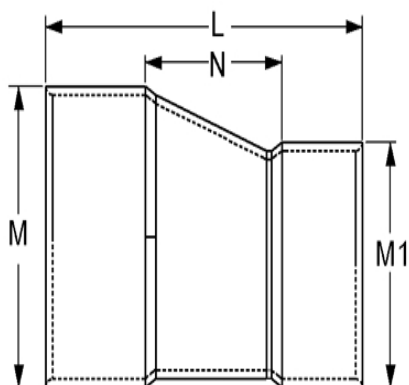

L = 16-5/16

N = 10-13/16

M = 7-1/8

M1 = 3-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

