

Part No: 3729-585E

Fabricated DWV

Couplings

Desc: 8X6 PVC RED COUP ECC SOC SCH40

MSRP: 126.13

Part Code: 390

Weight(lbs): 4.863

Weight(kg): 2.206

Weight(gm): 2206


Size: 8"X6"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Eccentric Reducer

Connection Socket x Socket

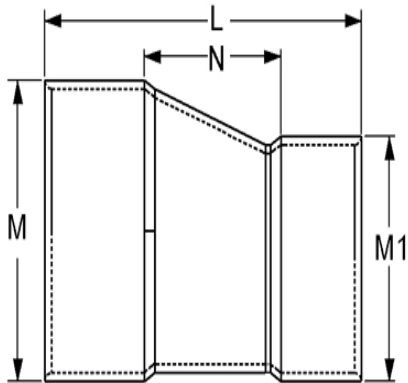

L = 14-3/8

N = 6-7/8

M = 9-3/16

M1 = 7-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

