

Part No: 3729-624E

Fabricated DWV

Couplings

Desc: 10X4 PVC RED COUP ECC SOC SCH40

MSRP: 356.8

Part Code: 390

Weight(lbs): 10.141

Weight(kg): 4.6

Weight(gm): 4600


Size: 10"X4"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Eccentric Reducer

Connection Socket x Socket

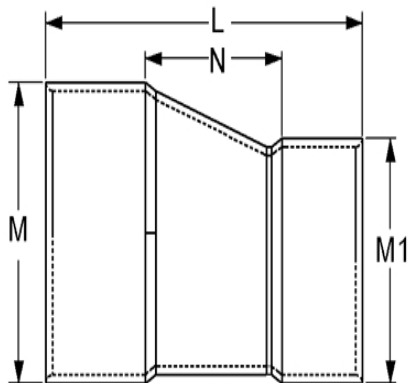

M = 11-3/8

M1 = 5

L = 22-7/16

N = 15-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

