

Part No: 3729-666

Fabricated DWV

Couplings

Desc: 12X6 PVC RED COUPLING SOC SCH40

MSRP: 481.82

Part Code: 390

Weight(lbs): 14.742

Weight(kg): 6.687

Weight(gm): 6687


Size: 12 X 6

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Reducing

Connection Socket x Socket

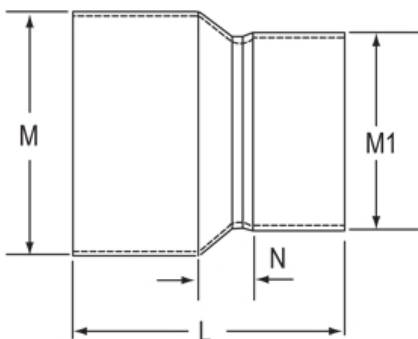

L = 20-1/2

M = 13-9/16

M1 = 7-1/4

N = 11

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

