

Part No: 3729-698E

Fabricated DWV

Couplings

Desc: 14X8 PVC RED COUP ECC SOC SCH40

MSRP: 910.27

Part Code: 390

Weight(lbs): 26.786

Weight(kg): 12.15

Weight(gm): 12150


Size: 14 X 8

Color: GRAY

Material: PVC

Schedule SCH 40 DWV- Eccentric Reducer

Connection Socket x Socket

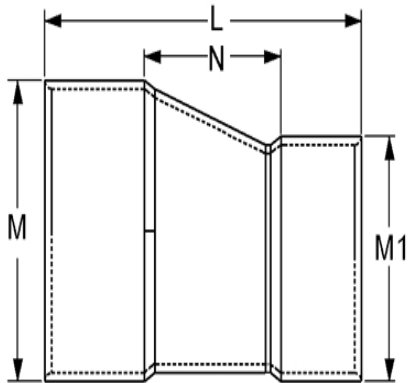

M = 15

M1 = 9-1/4

N = 19-1/16

L = 30-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

